


# cable socket ASI-SD-FK180

Part number: 196089

FESTO

For AS-i ribbon cable, profile turned 180°

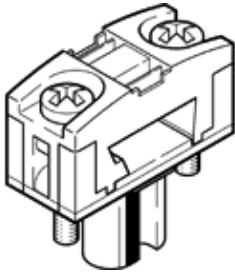

## Data sheet

Feature	Value
Mounting type	with through hole
Assembly position	Any
Product weight	6.2 g
Electrical connection	2-pin Plug socket, straight
Operating voltage range DC	$\leq 75$ V
Operating voltage range AC	$\leq 60$ V
Permissible current load	3 A
Terminal cross-section	1.5 mm <sup>2</sup>
Protection class	IP65
Ambient temperature with flexible cable installation	-5 ... 50 °C
Storage temperature	-30 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material housing	PA
Material electrical contact	Bronze