


# manifold block MHA1-PR4-3-PI-PCBM

Part number: 197253

FESTO

for mounting printed circuit boards of manifold block valves MHA1-...-PI, with pneumatic multi-pin plug.

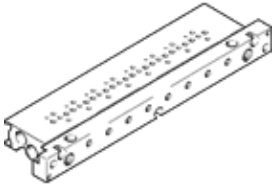

## Data sheet

| Feature                                 | Value   |
|---|---|
| Max. number of valve positions          | 4   |
| Operating pressure                      | 0 ... 8 bar   |
| Operating medium                        | Compressed air in accordance with ISO8573-1:2010 [7:4:4]                    |
| Note on operating and pilot medium      | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress   |
| PWIS conformity                         | VDMA24364-B2-L  |
| Ambient temperature                     | 0 ... 40 °C   |
| Mounting method for valve               | with internal (female) thread   |
| Pneumatic connection, port 1            | M5  |
| Pneumatic connection, port 2            | M3  |
| Pneumatic connection, port 3            | M5  |
| Material of connecting plate            | Wrought Aluminium alloy   |