


manifold block MHA1-PR10-3-PI-PCBM

Part number: 197256

FESTO

for mounting printed circuit boards of manifold block valves MHA1-...-PI, with pneumatic multi-pin plug.

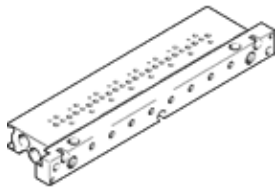

Data sheet

Feature	Value
Max. number of valve positions	10
Operating pressure	0 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	0 ... 40 °C
Mounting method for valve	with internal (female) thread
Pneumatic connection, port 1	M5
Pneumatic connection, port 2	M3
Pneumatic connection, port 3	M5
Material of connecting plate	Wrought Aluminium alloy