


# one-way flow control valve GR-3/4

Part number: 2103

FESTO

With flow adjustable in one direction.

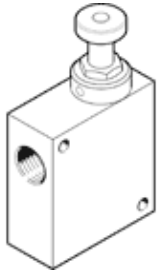

## Data sheet

Feature	Value
Valve function	One-way flow control function
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G3/4
Adjusting element	Knurled screw
Mounting type	Front panel installation with through hole
Standard nominal flow rate in flow control direction	3,300 l/min
Standard nominal flow rate in non-return direction	4800 l/min
Operating pressure	0.3 ... 15 bar
Ambient temperature	-10 ... 60 °C
Material housing	Wrought Aluminium alloy
Assembly position	Any
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Product weight	938 g
Materials note	Conforms to RoHS