


quick coupling plug KS4-CK-4

Part number: 2150

FESTO

For self-closing quick coupling connectors.

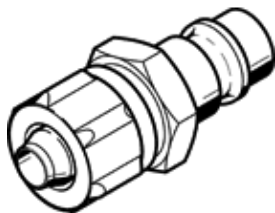

Data sheet

Feature	Value
Nominal size	2.9 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	252 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	26 g
Pneumatic connection, port 1	CK-4
Materials note	Conforms to RoHS