


butterfly valve

VZFB-D-40-WW-V4V4V

Part number: 2464962
Product to be discontinued

FESTO

Nominal width DN40, with welded ends, DIN 11850, FPM, material 1.4404.
Type to be discontinued. Available until 2022. See Support Portal for alternative products.

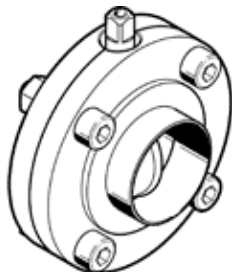

Data sheet

| Feature | Value |
|---|--|
| Design structure | 2-way disc valve |
| Type of actuation | manual |
| Sealing principle | soft |
| Assembly position | Any |
| Mounting type | Line installation |
| Process valve connection | Weld-on ends/weld-on ends |
| Nominal diameter DN | 40 |
| Flow direction | reversible |
| Nominal pressure of process valve | 10 |
| Actuation torque | 10 Nm |
| Based on the standard | DIN 11851 |
| Medium | Water Neutral fluids |
| Medium temperature | -15 ... 140 °C |
| Materials note | Contains PWIS substances Conforms to RoHS |
| Food-safe | See Supplementary material information |
| Material housing | High alloy steel, non-corrosive |
| Material number for housing | 1.4404 |
| Material disc | High alloy steel, non-corrosive |
| Material number for disc | 1.4404 |
| Material shaft | High alloy steel, non-corrosive |
| Material number for shaft | 1.4404 |
| Product weight | 1,100 g |
| Corrosion resistance classification CRC | 4 - Very high corrosion stress |