

butterfly valve


VZFB-D-50-WW-V2V2E

Part number: 2466725
 Product to be discontinued

FESTO

Nominal width DN50, with welded ends, DIN 11850, EPDM, material 1.4301.

Type to be discontinued. Available until 2022. See Support Portal for alternative products.

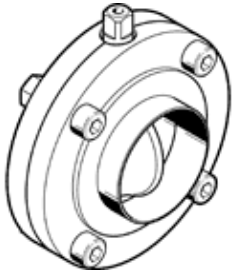

Data sheet

Feature	Value
Design structure	2-way disc valve
Type of actuation	manual
Sealing principle	soft
Assembly position	Any
Mounting type	Line installation
Process valve connection	Weld-on ends/weld-on ends
Nominal diameter DN	50
Flow direction	reversible
Nominal pressure of process valve	10
Actuation torque	14 Nm
Based on the standard	DIN 11851
Medium	Water Neutral fluids
Medium temperature	-10 ... 120 °C
Materials note	Contains PWIS substances Conforms to RoHS
Food-safe	See Supplementary material information
Material housing	High alloy steel, non-corrosive
Material number for housing	1.4301
Material disc	High alloy steel, non-corrosive
Material number for disc	1.4301
Material shaft	High alloy steel, non-corrosive
Material number for shaft	1.4301
Product weight	1,600 g
Corrosion resistance classification CRC	3 - High corrosion stress