


# butterfly valve

## VZFB-SZ-4"-TT-V4V4E

Part number: 2468273  
 Product to be discontinued

FESTO

Nominal width 4", with thread, SMS 1145, EPDM, material 1.4404.  
 Type to be discontinued. Available until 2022. See Support Portal for alternative products.

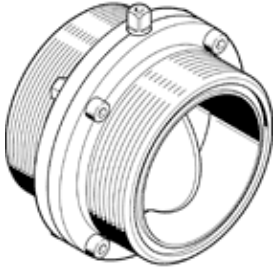

### Data sheet

Feature	Value
Design structure	2-way disc valve
Type of actuation	manual
Sealing principle	soft
Assembly position	Any
Mounting type	Line installation
Process valve connection	Male thread/male thread
Nominal diameter DN	4"
Flow direction	reversible
Nominal pressure of process valve	10
Actuation torque	35 Nm
Based on the standard	SMS 1145
Medium	Water Neutral fluids
Medium temperature	-10 ... 120 °C
Materials note	Contains PWIS substances Conforms to RoHS
Food-safe	See Supplementary material information
Material housing	High alloy steel, non-corrosive
Material number for housing	1.4404
Material disc	High alloy steel, non-corrosive
Material number for disc	1.4404
Material shaft	High alloy steel, non-corrosive
Material number for shaft	1.4404
Product weight	4,800 g
Corrosion resistance classification CRC	4 - Very high corrosion stress