


sub-base VABP-S1-1V1G-G14-2M-R3

Part number: 2614863

FESTO

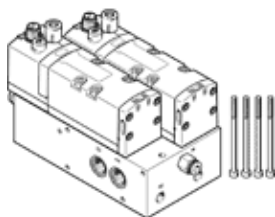

Data sheet

| Feature | Value |
|---|--|
| Width | 42 mm |
| Function port 32 | G1/8 |
| Function port 34 | G1/8 |
| Pneumatic port 22 | Sub-base G1/4 |
| Pneumatic port 44 | Sub-base G1/4 |
| Assembly position | Any |
| Operating pressure | 0 ... 16 bar |
| Pilot pressure | 3 ... 8 bar |
| Standard nominal flow rate | 1,400 l/min |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [6:4:4] |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Medium temperature | 0 ... 50 °C |
| Ambient temperature | 0 ... 50 °C |
| Product weight | 2,480 g |
| Pilot air port 14 | G1/8 |
| Pneumatic connection, port 2 | G1/4 |
| Pneumatic connection, port 4 | G1/4 |
| Materials note | Conforms to RoHS |
| Material manifold | Wrought Aluminium alloy |
| Material o-ring | NBR |
| Material screws | Steel |