


sub-base VABP-S1-2V1G-G38-2M-A1

Part number: 2738672

FESTO

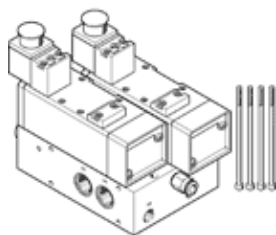

Data sheet

Feature	Value
Width	54 mm
Function port 32	G1/4
Function port 34	G1/4
Pneumatic port 22	Sub-base G3/8
Pneumatic port 44	Sub-base G3/8
Assembly position	Any
Operating pressure	0 ... 16 bar
Pilot pressure	3 ... 8 bar
Standard nominal flow rate	2,000 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [6:4:4]
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	0 ... 50 °C
Ambient temperature	0 ... 50 °C
Product weight	3,400 g
Pilot air port 14	G1/8
Pneumatic connection, port 2	G3/8
Pneumatic connection, port 4	G3/8
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminium alloy
Material o-ring	NBR
Material screws	Steel