


# parallel kit EAMM-U-70-D40-60H-96-S1

Part number: 2786137

FESTO

Suitable for electric drives.

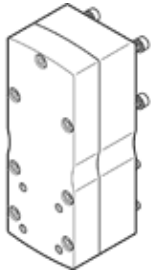

## Data sheet

| Feature                  | Value                 |
|--------------------------|-----------------------|
| Size                     | 70                    |
| Assembly position        | Any                   |
| Gear unit ratio          | 1:1                   |
| Max. speed               | 5,000 1/min           |
| PWIS conformity          | VDMA24364 zone III    |
| Storage temperature      | -25 ... 60 °C         |
| Relative air humidity    | 0 - 95 %              |
| Protection class         | IP65                  |
| Ambient temperature      | -10 ... 60 °C         |
| Mass moment of inertia   | 118 kgmm <sup>2</sup> |
| No-load driving torque   | 0.18 Nm               |
| Transferable torque      | 7 Nm                  |
| Product weight           | 1,760 g               |
| Interface code, actuator | D40B                  |
| Interface code, motor in | 60H                   |
| Materials note           | Conforms to RoHS      |