


bellows kit

EADB-V2-32-S101-200

Part number: 2828830

FESTO

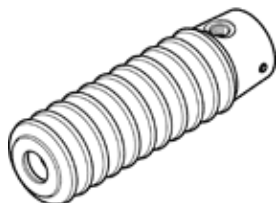

Data sheet

Feature	Value
Outside diameter	57 mm
Size	32
Stroke range	101 ... 200 mm
Piston rod extension	81 mm
Design	Round
Assembly position	Any
Design structure	Bellows kit with ducted exhaust air
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B2-L
Resistance to media	Dust Chippings Oils Grease Gasolines
Protection class	IP65 to IEC 60529
Ambient temperature	-10 ... 80 °C
Moving mass	85 g
Product weight	155 g
Mounting type	slip-on With threaded pin
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material adapter components	Wrought Aluminium alloy Anodised
Material seals	NBR
Material bellows	NBR
Material threaded pin	High alloy steel, non-corrosive