


manifold block MRS-4

Part number: 2844348

FESTO

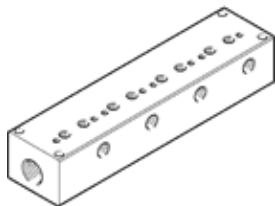

Data sheet

Feature	Value
Size	4
Max. number of valve positions	4
Operating pressure MPa	-0.09 ... 1 MPa
Operating pressure	-0.9 ... 10 bar
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque, valve mounting	2.5 Nm
Max. tightening torque, wall mounting	4 Nm
Product weight	650 g
Pneumatic connection, port 1	G3/8
Materials note	Conforms to RoHS
Material of connecting plate	Wrought Aluminium alloy