


# connecting cable KMC-1-230AC-2,5

Part number: 30932

FESTO

Pre-assembled, for C and N1 solenoids.

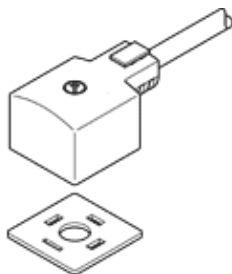

## Data sheet

Feature	Value
Authorisation	Germanischer Lloyd
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	170 g
Electrical connection	Plug socket Plug pattern type A to EN 175301-803
Nominal operating voltage, AC	230 V
Polarity protected	for all electrical connections
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	6 mm
Cable structure	3x0,75
Protection class	IP67 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE mark (see declaration of conformity)	to EU directive low-voltage devices in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PC
Material electrical contact	Bronze