


distributor block FR-9-M3-B

Part number: 30981

FESTO

For distribution of compressed air.

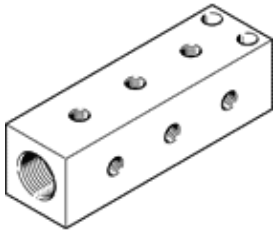

Data sheet

Feature	Value
Nominal size	2.5 mm
Assembly position	Any
Operating pressure complete temperature range	0 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 80 °C
Product weight	15 g
Number of outputs	9
Number of supply lines	1
Pneumatic connection, port 1	Female thread G1/8
Pneumatic connection, port 2	Female thread M3
Materials note	Conforms to RoHS
Material housing	Aluminium Anodised