


coupling
EAMC-56-58-19-20
Part number: 3181801

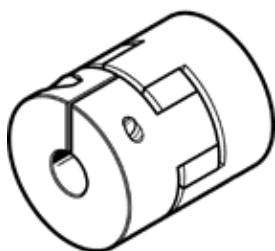

Data sheet

| Feature | Value |
|------------------------|-----------------------|
| Holder diameter 1 | 19 mm |
| Holder diameter 2 | 20 mm |
| Size | 56 |
| Nominal length | 58 mm |
| Assembly position | Any |
| Max. speed | 5,500 1/min |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Ambient temperature | -25 ... 60 °C |
| Mass moment of inertia | 128 kgmm ² |
| Transferable torque | 60 Nm |
| Product weight | 284 g |
| Materials note | Conforms to RoHS |