


Double DPZ-10-P-A

Part number: 32680

FESTO

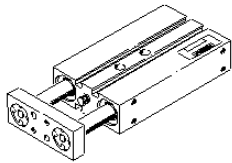

Datasheet

Feature	Value
Mode of operation	Double acting
Type of mounting	Circlip
Form, external	Profile
Form piston	Round
Form piston rod	Round
Sensing type	Magnetic
Type of cushioning	Internal cushioning ring (non-adjustable)
Protection against torsion	Parallel pistons
Piston, nominal size	10 mm
Stroke	0 mm
Piston rod diameter	6 mm
Overall length	89,6 mm
Operating pressure max.	10 bar
Minimum ambient temperature	-20 °C
Maximum ambient temperature	80 °C
Connection type bearing cap (EE)	Female thread
Thread type (bearing cap)	M
Thread diameter (metric)	5 mm
Silicone status	Free
Connection type cover cap	Thread
Thread type (cover cap)	M
Thread diameter (metric)	5 mm
Effective force (theor.) at 6 bar, adv	.94 N
Effect. force (theor.) at 6 bar, retur	n60 N
Air consumption at 6 bar, advance	0,012 L/<->
Air consumption at 6 bar, return	0,008 L/<->