


## non-return valve

### H-1/8-A/I

Part number: 3324

FESTO

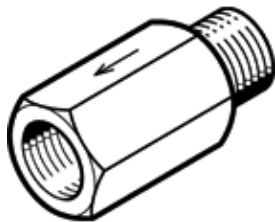

## Data sheet

Feature	Value
Valve function	Non-return function
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Mounting type	Line installation
Standard nominal flow rate	280 l/min
Operating pressure MPa	0.04 ... 0.8 MPa
Operating pressure	0.4 ... 8 bar
Ambient temperature	-10 ... 60 °C
Material housing	Brass
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B2-L
Medium temperature	-10 ... 60 °C
Product weight	21 g
Material seals	NBR