 



OR gate OS-1/2

Part number: 3427

FESTO

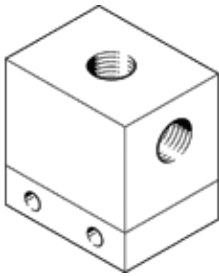

Data sheet

Feature	Value
Valve function	OR function
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G1/2
Mounting type	with through hole
Standard nominal flow rate	5,000 l/min
Operating pressure	1 ... 10 bar
Ambient temperature	-10 ... 60 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Nominal size	12 mm
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Pneumatic connection, port 3	G1/2
Materials note	Conforms to RoHS