

 

Solenoid valve

MYH-5/2-2,3-L-LED

Part number: 34303

FESTO

Mini Pneumatic, with solenoid coil and manual override, without plug socket.

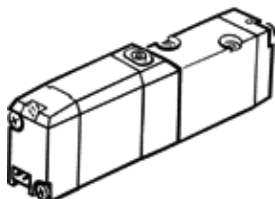

Data sheet

Feature	Value
Valve function	5/2 single solenoid
Standard nominal flow rate	180 l/min
Operating pressure	2 ... 8 bar
Design structure	Piston slide
Protection class	IP40 with plug socket
Nominal size	2.3 mm
Type of piloting	Piloted
Switching time off	23 ms
Switching time on	12 ms
Duty cycle	100%
Characteristic coil data	24V DC: 1,8W
Operating medium	Dried compressed air, lubricated or unlubricated
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
Product weight	65 g
Mounting type	with through hole
Pneumatic connection, port 1	Sub-base Manifold module
Pneumatic connection, port 2	Sub-base Manifold module
Pneumatic connection, port 3	Sub-base Manifold module
Pneumatic connection, port 4	Manifold module
Pneumatic connection, port 5	Manifold module
Materials information for seals	NBR
Materials information, housing	Aluminium die cast