

 

# Solenoid valve

## MYH-5/3E-2,3-L-LED

Part number: 34306

FESTO

Mini Pneumatic, with solenoid coil and manual override, without plug socket.

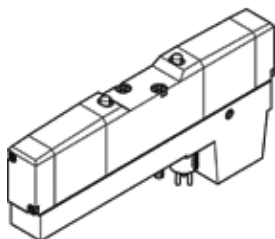

## Data sheet

Feature	Value
Valve function	5/3 exhausted
Standard nominal flow rate	125 l/min
Operating pressure	2 ... 8 bar
Design structure	Piston slide
Protection class	IP40 with plug socket
Nominal size	2.3 mm
Type of piloting	Piloted
Switching time off	33 ms
Switching time on	8 ms
Duty cycle	100%
Characteristic coil data	24V DC: 1,8W
Operating medium	Dried compressed air, lubricated or unlubricated
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
Product weight	105 g
Mounting type	with through hole
Pneumatic connection, port 1	Sub-base Manifold module
Pneumatic connection, port 2	Sub-base Manifold module
Pneumatic connection, port 3	Sub-base Manifold module
Pneumatic connection, port 4	Manifold module
Pneumatic connection, port 5	Manifold module
Materials information for seals	NBR
Materials information, housing	Aluminium die cast