

 

Solenoid valve

JMYH-5/2-M5-L-LED

Part number: 34310

FESTO

With solenoid coils and manual override, without plug sockets.

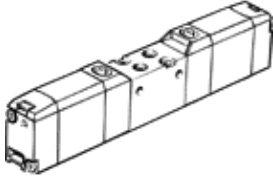

Data sheet

Feature	Value
Valve function	5/2 bistable
Standard nominal flow rate	190 l/min
Operating pressure	2 ... 8 bar
Design structure	Piston slide
Protection class	IP40 with plug socket
Nominal size	2.3 mm
Type of piloting	Piloted
Switching time reversal	7 ms
Duty cycle	100%
Characteristic coil data	24V DC: 1,8W
Operating medium	Dried compressed air, lubricated or unlubricated
Medium temperature	-5 ... 50 °C
Ambient temperature	-5 ... 50 °C
Product weight	95 g
Mounting type	with through hole
Pneumatic connection, port 1	Sub-base M5
Pneumatic connection, port 2	Sub-base M5
Pneumatic connection, port 3	Sub-base M5
Pneumatic connection, port 4	Sub-base
Pneumatic connection, port 5	Sub-base
Materials information for seals	NBR
Materials information, housing	Aluminium die cast