


Swivel flange SNGB-100

Part number: 34545
Product to be discontinued

FESTO

For cylinders DNG, DNGU; matching clevis foot mountings LN, LSN.
Type to be discontinued. Available until 2014. See Support Portal for alternative products.

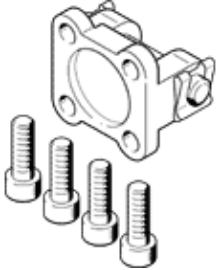

Data sheet

Feature	Value
Size	100
Based on the standard	ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance classification CRC	2
Ambient temperature	-40 ... 90 °C
Product weight	1,040 g
Materials note	Free of copper and PTFE Conforms to RoHS
Material information, mounting	Aluminium die cast
Material information, bolt	Steel Galvanised
Materials information for bearing	Plastic
Screw material data	Steel Galvanised
Material information for fuse	Spring steel, galvanised