


swivel flange SNGB-160

Part number: 34547

FESTO

Suitable clevis foot LN, LSN.

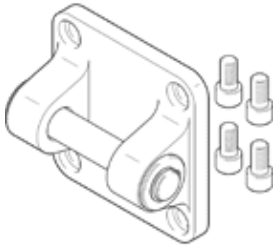

Data sheet

Feature	Value
Size	160
Based on the standard	ISO 15552 (previously also VDMA 24652, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-40 ... 90 °C
Product weight	3,445 g
Materials note	Conforms to RoHS
Material mounting	Aluminium die cast
Material mounting pin	Steel Galvanised
Material bearing	Plastic
Material disc	steel, galvanized
Material screws	Steel Galvanised
Material lock	Spring steel, galvanised