 



# intermediate pressure regulator plate LR-ZP-A/B-D-3

Part number: 35429

FESTO

For ISO valves.

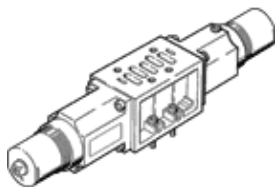

## Data sheet

Feature	Value
Based on the standard	ISO 5599-1
Integrated function	Pressure regulator
Design structure	Piston
Pressure regulation range	0.5 ... 12 bar
Inlet pressure 1	$\leq 14$ bar
Authorisation	UL - Recognized (OL)
PWIS conformity	VDMA24364 zone III
Product weight	1,770 g
Materials note	Conforms to RoHS
Material seals	NBR
Material housing	Aluminium die cast Steel