


barbed L-fitting LCNH-1/8-PK-6

Part number: 35987

FESTO

Rotatable, with extended housing, for plastic tubing PAN, PUN, PP, PU, PR, with sealing ring.

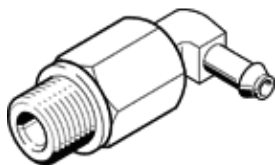

Data sheet

| Feature | Value |
|---|---|
| Nominal size | 4.9 mm |
| Type of seal on screw-in stud | Sealing ring |
| Operating pressure complete temperature range | -0.95 ... 10 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | 0 ... 60 °C |
| Pneumatic connection, port 1 | Male thread G1/8 |
| Pneumatic connection, port 2 | For tubing outside diameter 8 mm |
| Materials note | Conforms to RoHS |
| Material housing | Aluminium Zinc die-casting |