


coupling

EAMD-25-22-9-10X12

Part number: 3717923

FESTO

drive component, which transmits the rotary motion of a stepper or servo motor

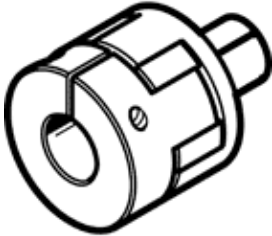

Data sheet

| Feature | Value |
|------------------------|-----------------------|
| Holder diameter 1 | 9 mm |
| Holder diameter 2 | 10 mm |
| Size | 25 |
| Nominal length | 22 mm |
| Assembly position | Any |
| Max. speed | 8,000 1/min |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Ambient temperature | -25 ... 60 °C |
| Mass moment of inertia | 3.2 kgmm ² |
| Transferable torque | 9 Nm |
| Product weight | 43.2 g |
| Materials note | Conforms to RoHS |