


Adaptive Gripper Finger DHAS-GF-60-U-BU

Part number: 3998967

FESTO

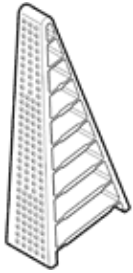

Data sheet

Feature	Value
Size	60
Assembly position	Any
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
RSBP classification to CD-0033	F1a
Food-safe	See Supplementary material information
Ambient temperature	10 ... 50 °C
Product weight	7 g
Materials note	Conforms to RoHS
Material clamp jaws	TPE-U(PU)