


quick coupling plug KS2-CK-3

Part number: 4091

FESTO

For self-closing quick coupling connectors.

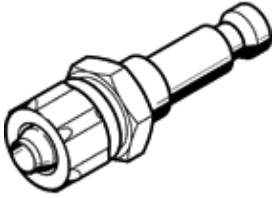

Data sheet

| Feature | Value |
|---|--|
| Nominal size | 2 mm |
| Operating pressure complete temperature range | -0.95 ... 12 bar |
| Standard nominal flow rate | 68 l/min |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 ... 60 °C |
| Product weight | 4 g |
| Pneumatic connection, port 1 | CK-3 |
| Materials note | Conforms to RoHS |