 



pneumatic valve VL/O-3-PK-3X2

Part number: 4245

FESTO

Depending on the choice of connection, normally-open or normally-closed function.

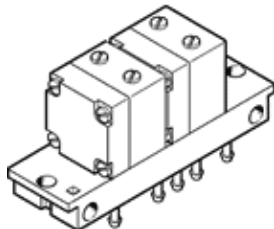

Data sheet

Feature	Value
Valve function	3/2 open, monostable
Standard nominal flow rate	100 l/min
Operating pressure	0 ... 8 bar
Design structure	Poppet seat
Nominal size	2.5 mm
Switching time off	50 ms
Switching time on	12 ms
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Pilot medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Ambient temperature	-10 ... 60 °C
Product weight	180 g
Mounting type	On sub-base On mounting frame with through hole Optional
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 4	PK-3
Pneumatic connection, port 5	PK-3
Material of connecting plate	Brass PPS-reinforced
Material seals	NBR
Material housing	Plastic Zinc die-casting