

 

# solenoid valve

## JMFH-5-PK-3

Part number: 4447

FESTO

With manual overrides, without solenoid coils or sockets. Solenoid coils and sockets should be ordered separately.

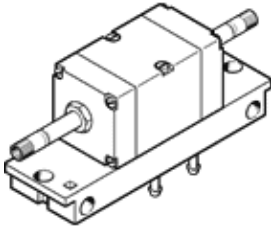

## Data sheet

Feature	Value
Valve function	5/2 bistable
Standard nominal flow rate	105 l/min
Operating pressure	2 ... 8 bar
Design structure	Poppet seat
Nominal size	2.5 mm
Sealing principle	soft
Switching time reversal	13 ms
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	0 ... 60 °C
Ambient temperature	0 ... 40 °C
Product weight	380 g
Mounting type	On sub-base On mounting frame with through hole Optional
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Pneumatic connection, port 3	PK-3
Pneumatic connection, port 4	PK-3
Pneumatic connection, port 5	PK-3
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium Anodised
Material seals	NBR
Material housing	Aluminium Anodised