


solenoid coil

MSFW-24-50/60

Part number: 4534

FESTO

With standard plug socket

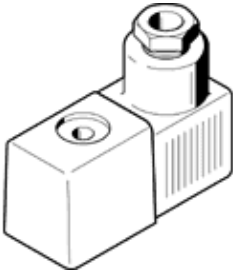

Data sheet

| Feature | Value |
|-------------------------------------|---|
| Assembly position | Any |
| Switching position indicator | No |
| Min. pickup time | 10 ms |
| Duty cycle | 100 % |
| Power factor cos {phi} | 0.7 |
| Characteristic coil data | 24 V AC: 50/60 Hz, pick-up power 9 VA, holding power 7 VA |
| Permissible frequency fluctuation | +/- 5 % |
| Permissible voltage fluctuation | +/- 10 % |
| PWIS conformity | VDMA24364-C1-L |
| Protection class | IP65 |
| Ambient temperature | -5 ... 40 °C |
| Max. tightening torque, plug socket | 0.4 Nm |
| Product weight | 55 g |
| Electrical connection | 3-pin Plug vanes for MSSD-F |
| Mounting type | With knurled nut |
| Materials note | Conforms to RoHS |
| Material solenoid coil | Duroplast Copper Steel |
| Material winding | Copper |