


# sub-base VABS-S7-RB-B-N14-V14-A

Part number: 4727331

FESTO

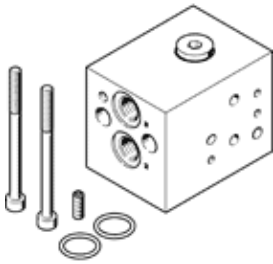

## Data sheet

| Feature                                 | Value  |
|---|--|
| Assembly position                       | Any  |
| Pilot air supply                        | external<br>Internal                                     |
| Operating pressure MPa                  | 0 ... 1 MPa  |
| Operating pressure                      | 0 ... 10 bar   |
| Operating medium                        | Compressed air in accordance with ISO8573-1:2010 [-:-:-] |
| Corrosion resistance classification CRC | 4 - Very high corrosion stress                           |
| PWIS conformity                         | VDMA24364 zone III                                       |
| Protection class                        | IP65   |
| Mounting type                           | with through hole  |
| Pilot air port 12                       | 1/4 NPT  |
| Pneumatic connection, port 1            | 1/4 NPT  |
| Pneumatic connection, port 2            | Flange 1/4<br>NAMUR port pattern                         |
| Pneumatic connection, port 3            | 1/4 NPT  |
| Materials note                          | Conforms to RoHS   |
| Material of connecting plate            | Aluminium (Ematal coated)                                |
| Material seals                          | NBR  |