


# coupling

## EAMD-16-15-6-8X10

Part number: 4819883

FESTO

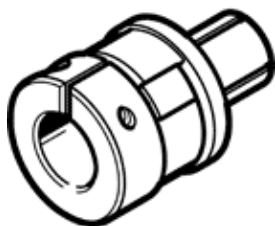

### Data sheet

Feature	Value
Holder diameter 1	6 mm
Holder diameter 2	8 mm
Size	16
Nominal length	15 mm
Assembly position	Any
Max. speed	10,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	0.355 kgmm <sup>2</sup>
Transferable torque	1.5 Nm
Product weight	12.8 g
Materials note	Conforms to RoHS