 



# EMC-filter CAMF-C5-FC

Part number: 4825847  
Product to be discontinued

FESTO

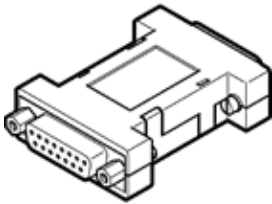

## Data sheet

Feature	Value
Operating voltage range DC	0 ... 30 V
Nominal operating voltage DC	24 V
Operating voltage range AC	0 ... 30 V
Nominal operating voltage, AC	24 V
PWIS conformity	VDMA24364-B2-L
Protection class	IP30
Note on degree of protection	in assembled condition
Ambient temperature	-40 ... 80 °C
Materials note	Conforms to RoHS
Electrical connection 1, function	Field device side
Electrical connection 1, design	Angular
Electrical connection 1, connection type	Plug socket
Electrical connection 1, cable outlet	Straight
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	15
Electrical connection 1, occupied pins/wires	8
Electrical connection 2, function	Controller side
Electrical connection 2, design	Angular
Electrical connection 2, connection type	Plug
Electrical connection 2, cable outlet	Straight
Electrical connection 2, connection technology	Sub-D
Electrical connection 2, number of pins/wires	15
Electrical connection 2, occupied pins/wires	8
Electrical connection 2, type of mounting	2x screw 4-40 UNC-2A
Protocol	HIPERFACE
Housing colour	silver
Material housing	Plastic, metallised