


**coupling**  
**EAMD-25-22-12-10X12**  
Part number: 5029897

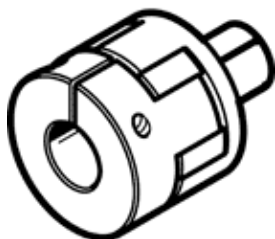

**Data sheet**

| Feature                | Value                 |
|------------------------|-----------------------|
| Holder diameter 1      | 12 mm                 |
| Holder diameter 2      | 10 mm                 |
| Size                   | 25                    |
| Nominal length         | 22 mm                 |
| Assembly position      | Any                   |
| Max. speed             | 8,000 1/min           |
| PWIS conformity        | VDMA24364-B2-L        |
| Storage temperature    | -25 ... 60 °C         |
| Relative air humidity  | 0 - 95 %              |
| Ambient temperature    | -25 ... 60 °C         |
| Mass moment of inertia | 3.2 kgmm <sup>2</sup> |
| Transferable torque    | 9 Nm                  |
| Product weight         | 42.1 g                |
| Materials note         | Conforms to RoHS      |