


manifold block MHA4-PR10-3-1/4

Part number: 525238

FESTO

[For sub-base valves MHA4-...](#)

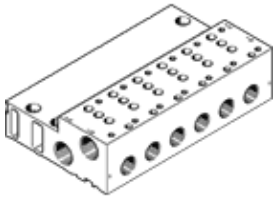

Data sheet

Feature	Value
Max. number of valve positions	10
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Product weight	1,710 g
Mounting method for sub-base	with through hole with top-hat rail
Mounting method for valve	with internal (female) thread
Pneumatic ports 1/33	G3/8
Pneumatic connection, port 2	Female thread 1/4
Pneumatic ports 3/11	G3/8
Material of connecting plate	Wrought Aluminium alloy