


# Manifold block VIGK-04-D-2-1/2-NPT

Part number: 525574

FESTO

For valve terminal 04, high flow rate, size 2 ISO valves (G 1/2)

This product is only available if ordered from the Festo Corporation, USA.

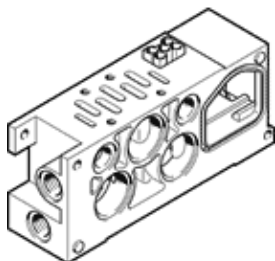

## Data sheet

Feature	Value
Width	183 mm
Operating pressure	-0.9 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Medium temperature	-10 ... 60 °C
Protection class	IP65
Ambient temperature	-10 ... 60 °C
Mounting method for sub-base	with through hole
Auxiliary pilot air port 12/14	NPT1/8-27
Pneumatic connection, port 1	NPT3/4-14
Pneumatic connection, port 2	NPT1/2-14
Pneumatic connection, port 3	NPT3/4-14
Pneumatic connection, port 4	NPT1/2-14
Pneumatic connection, port 5	NPT3/4-14
Materials information for sub-base	Aluminium die cast