


# connecting cable KMYZ-3-24-M8-0,5-LED-PUR

Part number: 525654

FESTO

highly flexible, for fast-switching valves MH2/MH3 and multi-pin distributor MPV

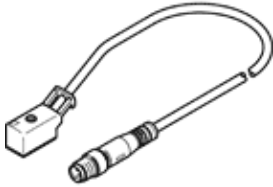

## Data sheet

Feature	Value
Assembly position	Any
Switching position indicator	LED
Protection class	IP65
Ambient temperature	-10 ... 50 °C
Tightening torque	0.25 Nm
Product weight	18 g
Electrical connection	angled socket / straight plug square design / M8x1 2-pin / 3-pin
Cable structure	2x0,25
Cable diameter	3.4 mm
Cable length	0.5 m
Protective earth connection	Not available
Mounting type	On solenoid valve with M2 central screw
Materials note	Conforms to RoHS
Materials information, housing	PA
Materials information, cable sheaths	TPE-U(PUR)
Material information for crimp connectors	Bronze