


intermediate position attachment SLG-Z-18-A

Part number: 525681

FESTO

For linear drive SLG

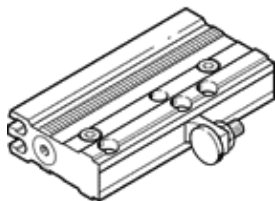

Data sheet

Feature	Value
Assembly position	Any
Design structure	Swivel module
Position detection	For proximity sensor
Operating pressure	1 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 60 °C
Product weight	75 g
Mounting type	With through-hole and dowel pin
Pneumatic connection	M3
Material stops	Steel, nickel-plated
Material seals	PUR
Material housing	Aluminium Hard anodised