


suction cup ESS-40-BT-M6

Part number: 525989

FESTO

easily interchangeable,

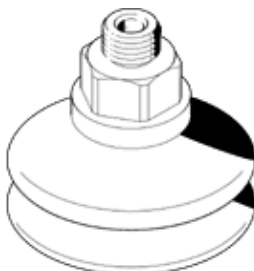

Data sheet

Feature	Value
Height compensator for suction-cup holder	9 mm
Min. workpiece radius	35 mm
Nominal size	2.5 mm
suction cup diameter	40 mm
suction cup volume	9.8 cm ³
Assembly position	Any
Correlation to suction-cup holder	Size 4
Suction cup shape	Round, bellows 1.5 conv
Operating pressure	-0.95 ... 0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-10 ... 80 °C
Retention force at nominal operating pressure	59 N
Lateral force at nominal operating pressure	22 N
Product weight	18 g
Mounting type	Via vacuum port
Vacuum connection	M6
Colour	red/brown
Shore hardness	72 +/- 5
Material of threaded plug	Wrought Aluminium alloy
Materials note	Conforms to RoHS
Material suction cup	Vulkollan®