 



suction cup ESS-50-BT-M10

Part number: 525994

FESTO

easily interchangeable,

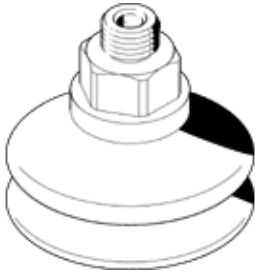

Data sheet

Feature	Value
Height compensator for suction-cup holder	10 mm
Min. workpiece radius	40 mm
Nominal size	2.5 mm
suction cup diameter	50 mm
suction cup volume	17.6 cm ³
Assembly position	Any
Correlation to suction-cup holder	Size 5
Suction cup shape	Round, bellows 1.5 conv
Operating pressure	-0.95 ... 0 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7::-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-10 ... 80 °C
Retention force at nominal operating pressure	100 N
Lateral force at nominal operating pressure	39 N
Product weight	25 g
Mounting type	Via vacuum port
Vacuum connection	M10
Colour	red/brown
Shore hardness	72 +/- 5
Material of threaded plug	Wrought Aluminium alloy
Materials note	Conforms to RoHS
Material suction cup	Vulkollan®