


# Plastic PP-3-NT-P

Part number: 526192

FESTO

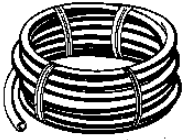

## Datasheet

Feature	Value
Nominal size of tubing	3
Internal diameter	2,9 mm
Outside diameter	4 mm
Bending radius min.	18 mm
Operating pressure min.	-0,95 bar
Operating pressure max. at 20°C	14,5 bar
Operating pressure max. at 30°C	12,5 bar
Operating pressure max. at 40°C	10,5 bar
Operating pressure max. at 50°C	9,5 bar
Operating pressure max. at 60°C	8,5 bar
Operating pressure max. at 70°C	7,5 bar
Operating pressure max. at 80°C	7 bar
Suitable for vacuum	Yes
Minimum ambient temperature	-30 °C
Maximum ambient temperature	80 °C
Product weight per meter	0,0062 kg/m
Color	Neutral