


electrical plug-in base MHAP-PI-D-0.5

Part number: 529116

FESTO

For valve terminal CPA-SC, two coils.

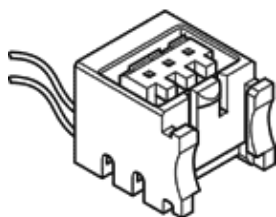

Data sheet

Feature	Value
Mounting type	Clip
Assembly position	Any
Product weight	5 g
Electrical connection	Plug socket 3-pin
Operating voltage range DC	≤ 60 V
Permissible current load	3 A
Cable length	0.5 m
Cable diameter	1 mm
Cable structure	3x0,14
Protection class	IP40
Ambient temperature	-20 ... 80 °C
Ambient temperature with flexible cable installation	-20 ... 50 °C
Materials note	Conforms to RoHS
Materials information, housing	PA
Material information for crimp connectors	Copper Galvanised