


# coupling socket KD4-CK-6

Part number: 531639

FESTO

Self-closing

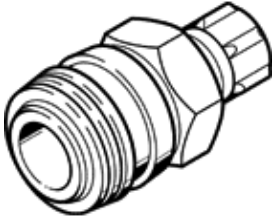

## Data sheet

Feature	Value
Nominal size	4.9 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	432 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	63 g
Pneumatic connection, port 1	CK-6
Materials note	Conforms to RoHS