


quick coupling socket KDS6-1/4-I

Part number: 531650
Product to be discontinued

FESTO

Self-closing, for safety coupling per ISO 4414
Type to be discontinued. Available until 2018. See Support Portal for alternative products.

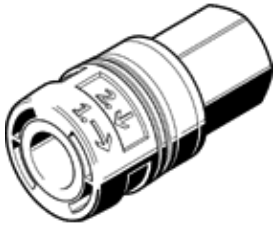

Data sheet

Feature	Value
Nominal size	7.2 mm
Operating pressure complete temperature range	-0.5 ... 12 bar
Standard nominal flow rate	1,373 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Authorisation	BIA TÜV
Nominal tightening torque	9.5 Nm
Tolerance for nominal tightening torque	± 15 %
Product weight	125 g
Pneumatic connection, port 1	Female thread 1/4
Materials note	Conforms to RoHS