


# quick coupling socket KDS6-1/2-I

Part number: 531652  
Product to be discontinued

FESTO

Self-closing, for safety coupling per ISO 4414  
Type to be discontinued. Available until 2018. See Support Portal for alternative products.

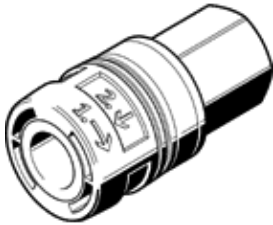

## Data sheet

Feature	Value
Nominal size	7.2 mm
Operating pressure complete temperature range	-0.5 ... 12 bar
Standard nominal flow rate	1,782 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Authorisation	BIA TÜV
Nominal tightening torque	32.5 Nm
Tolerance for nominal tightening torque	± 20 %
Product weight	121 g
Pneumatic connection, port 1	Female thread G1/2
Materials note	Conforms to RoHS