


quick coupling socket KDS6-CK-13

Part number: 531654
Product to be discontinued

FESTO

Self-closing, for safety coupling per ISO 4414
Type to be discontinued. Available until 2018. See Support Portal for alternative products.

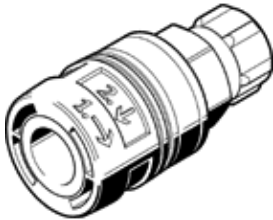

Data sheet

| Feature | Value |
|---|--|
| Nominal size | 10 mm |
| Operating pressure complete temperature range | -0.5 ... 12 bar |
| Standard nominal flow rate | 1,697 l/min |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| Ambient temperature | -10 ... 60 °C |
| Authorisation | BIA TÜV |
| Product weight | 121 g |
| Pneumatic connection, port 1 | CK-13 |
| Materials note | Conforms to RoHS |