


quick coupling plug KS3-1/8-A-R

Part number: 531667

FESTO

With non-return valve for self-closing quick coupling connectors on both sides

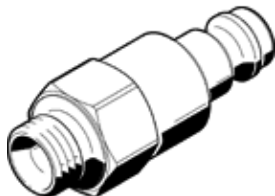

Data sheet

Feature	Value
Nominal size	4.2 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Nominal tightening torque	5 Nm
Tolerance for nominal tightening torque	± 15 %
Product weight	32 g
Pneumatic connection, port 1	Male thread G1/8
Materials note	Conforms to RoHS