


quick coupling plug KS4-3/8-I

Part number: 531679

FESTO

For self-closing quick coupling connectors.

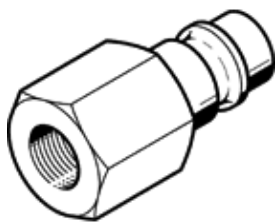

Data sheet

Feature	Value
Nominal size	7.85 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	1,350 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Nominal tightening torque	21.5 Nm
Tolerance for nominal tightening torque	± 15 %
Product weight	32 g
Pneumatic connection, port 1	Female thread G3/8
Materials note	Conforms to RoHS